



Variante A
Schaltschrankaufbau
SIEMENS\AUTOMATION_TECHNOLOGY\POWER SUPPLIES\6EP1931-2FC42_2D.ema

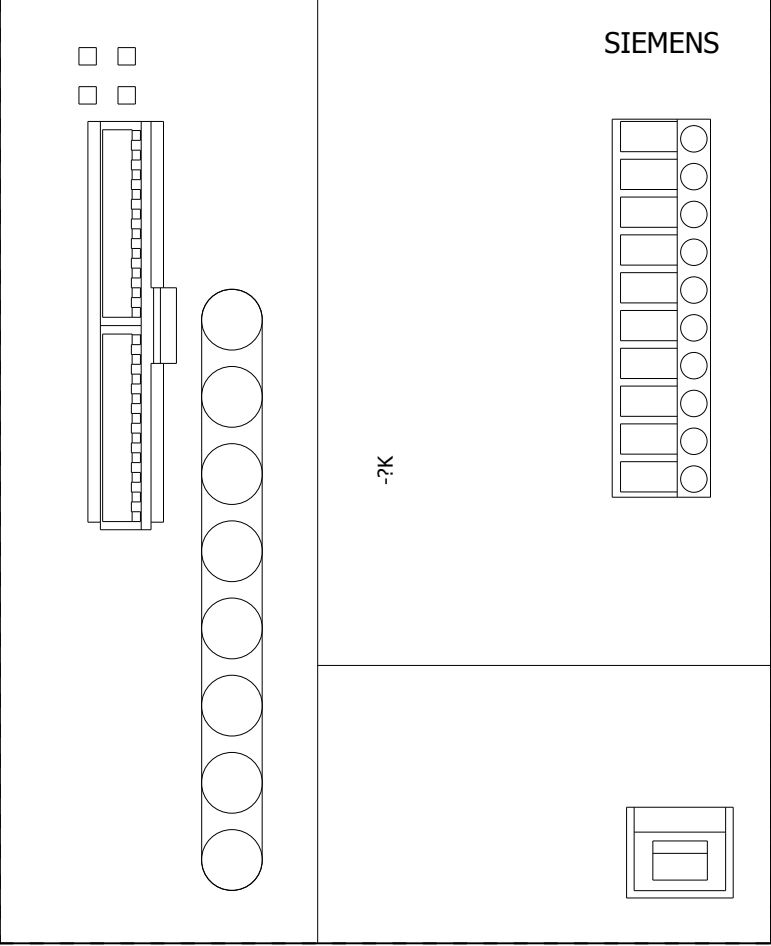

Variante A
Allpolig
SIEMENS\AUTOMATION_TECHNOLOGY\POWER SUPPLIES\6EP1931-2FC42_2D.ema

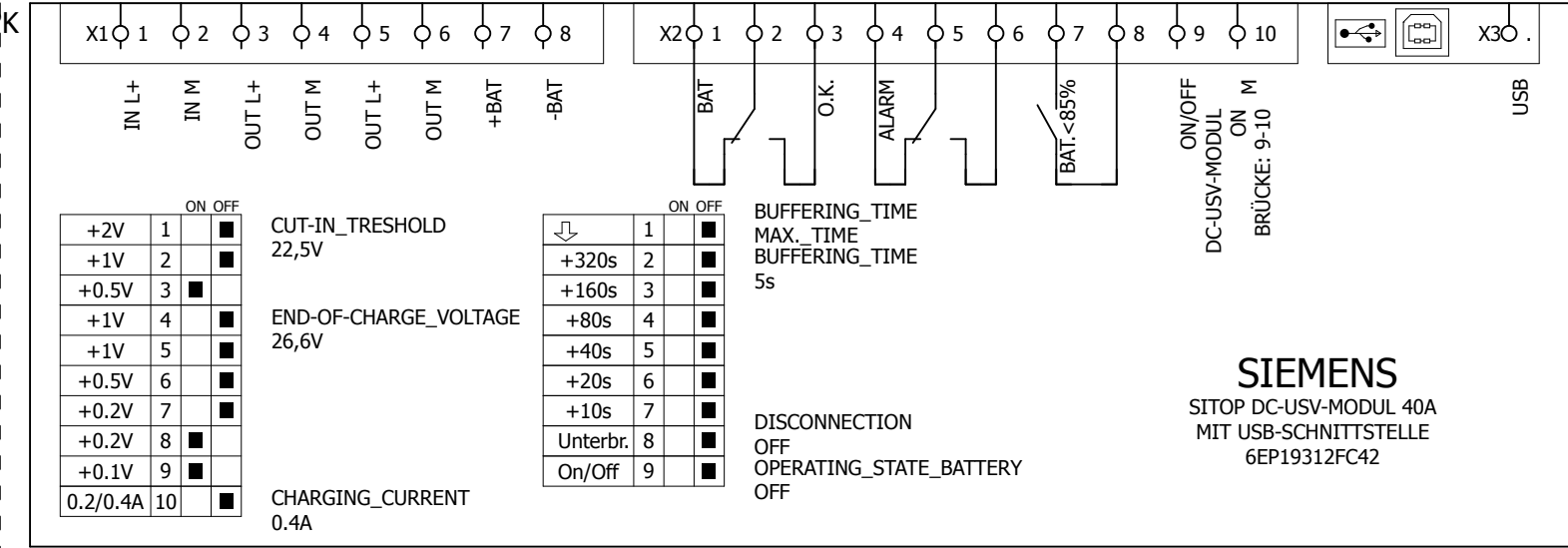

ON

OFF

+2V

1

+1V

2

+0.5V

3

+1V

4

+1V

5

+0.5V

6

+0.2V

7

+0.2V

8

+0.1V

9

0.2/0.4A

10

CUT-IN_TRESHOLD

22,5V

END-OF-CHARGE_VOLTAGE

26,6V

CHARGING_CURRENT

0.4A

ON

OFF

↓

1

+320s

2

+160s

3

+80s

4

+40s

5

+20s

6

+10s

7

Unterbr.

8

On/Off

9

BUFFERING_TIME

MAX_TIME

BUFFERING_TIME

5s

DISCONNECTION

OFF

OPERATING_STATE_BATTERY

OFF


SIEMENS

SITOP DC-USV-MODUL 40A

MIT USB-SCHNITTSTELLE

6EP19312FC42

Variante A
Einpölig
SIEMENS\AUTOMATION_TECHNOLOGY\POWER SUPPLIES\6EP1931-2FC42_2D.ema

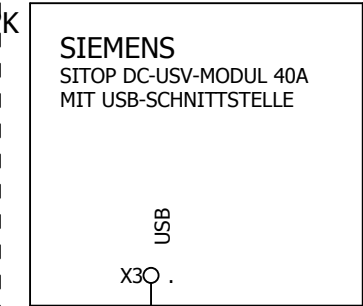

==SIEMENS=AUTOMATION_TECHNOLOGY++POWER SUPPLIES+6EP1931-2FC42_2D>MASTER 109 // USV #109.5-?K

Eigenschaften

Artikeleigenschaften

Artikel: SIE.6EP1931-2FC42

Bestellnummer	6EP19312FC42
Bezeichnung 1	SITOP DC-USV-MODUL 40A
Bezeichnung 2	MIT USB-SCHNITTSTELLE
Beschreibung	SITOP DC-USV-MODUL 24 V/40 A UNTERBRECHUNG SFREIE STROMVERSORGUNG MIT USB-SCHNITTST ELLE EINGANG: DC 24 V/42,6 A AUSGANG: DC 24 V/ 40 A
Breite	102,00 mm
Höhe	125,00 mm
Tiefe	133,50 mm
Gewicht	1,10 kg
Artikel/Technische Kenngrößen	In: DC 24 V/42,6 A Out: DC 24 V/40 A
Artikel/Menge/Verpackung	1,00
Artikel/Strichcode-Nummer	4025515151425
Artikel/Externes Dokument 1	6EP19312FC42_de
Artikel/Externes Dokument 2	6EP19312FC42_en
Artikel/Externes Dokument 4	https://support.automation.siemens.com/WW/view/de/6EP1931-2FC42
Artikel/Externes Dokument 5	https://support.automation.siemens.com/WW/view/en/6EP1931-2FC42
Artikel/Externes Dokument 6	https://support.automation.siemens.com/WW/view/fr/6EP1931-2FC42
Artikel/Externes Dokument 7	https://support.automation.siemens.com/WW/view/es/6EP1931-2FC42